


Interconnect Solutions for Delivery Robot: LiDAR, Camera, Sensor, Wireless and FAN Module Connections

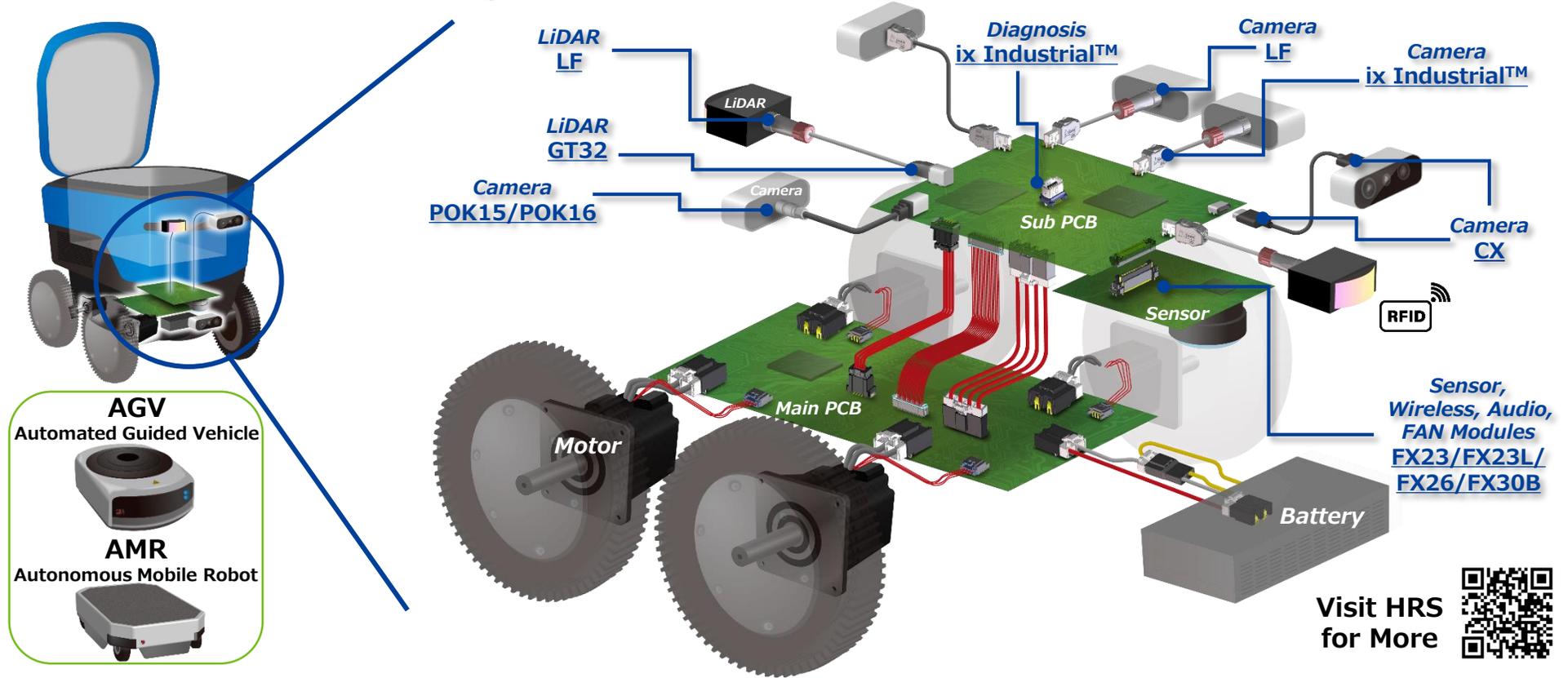

LiDAR & Camera

Sensor, Wireless, and FAN Modules



ix Industrial™
Compact and Robust
Cat.6A I/O



CX Series
USB Type-C Connector
Supporting Up to 20Gbps



GT32 Series
1Gbps, Space-saving
Shielded Signal I/O



POK15/POK16 Series
3GHz, Coaxial
Wire-to-Board &
Board-to-Board



LF Series
Shielded
Waterproof I/O



FunctionMAX™
FX23/FX23L Series
High Speed Floating
Board-to-Board with
Power Contacts




FunctionMAX™
FX26 Series
Vibration Absorbing,
Floating
Board-to-Board



FunctionMAX™
FX30B Series
Board-to-Board
Power Connectors
With Misalignment
Absorption

Interconnect Solutions for Delivery Robot: Motor Signal, PCB, Motor Power and Battery Connections

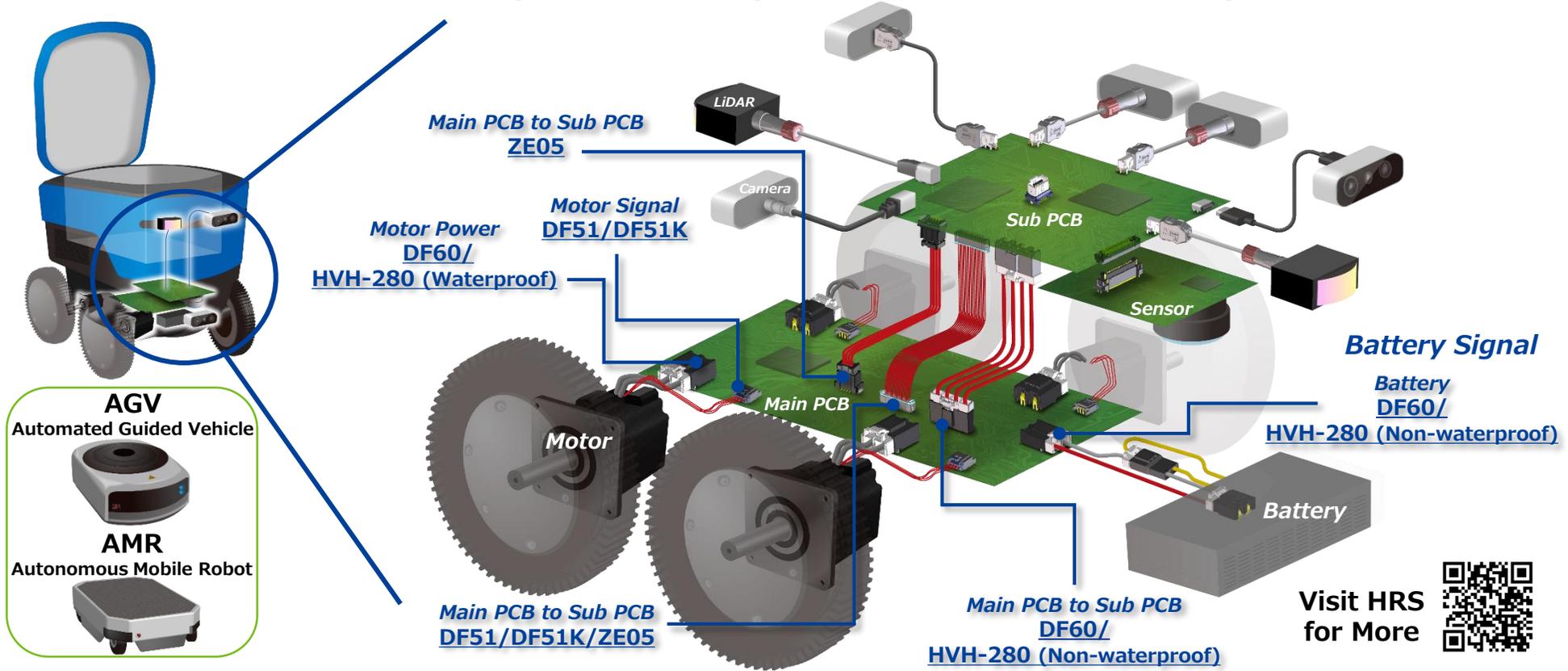

Visit HRS for More




Motor Signal & PCB

Automotive Grade



ZE05 Series
125°C Heat Resistant,
High Vibration Resistance

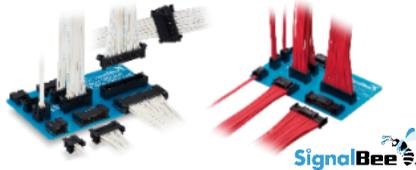

DF51/DF51K Series
2mm Pitch,
Positive Lock
Wire-to-Board



DF60 Series
65A Max.*Current,
Positive Lock
Wire-to-Board
*UL Standard

Motor Power & Battery

Automotive Grade



HVH-280 (Non-waterproof) Series
125°C Heat Resistant,
30A Wire-to-Board

Automotive Grade



HVH-280 (Waterproof) Series
30A Waterproof
Panel Mount I/O